



CONTEG[®]
to complete your network



Headquarters Czech Republic:
Tel.: +420 261 219 182, Fax: +420 261 219 192
conteg@conteg.com, www.conteg.com

Czech Republic: +420 724 914 613
Eastern Europe: +49 172 848 4346
France: +33 686 074 386
GER, SUI, AUT: +49 170 523 4958
Middle East: +971 50 565 6334
Russia: +7 495 506 13 28
Western Europe: +32 476 215 089


Cut Sheet

AC-WM-30

Cut_Sheet_EN_21-08-08_conteg ©

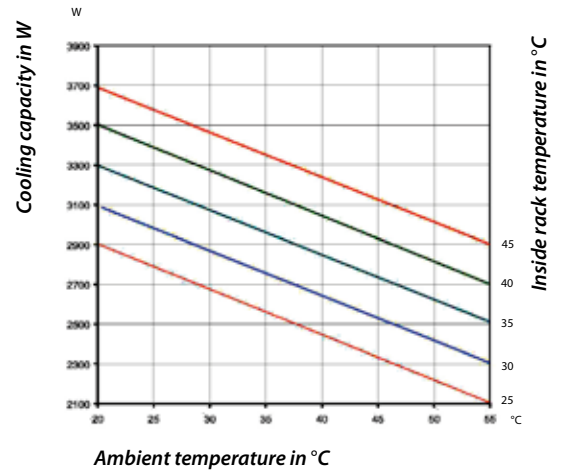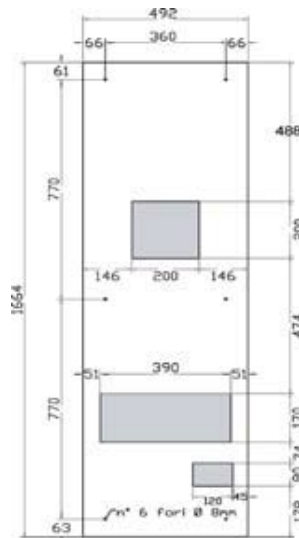

Ambient temperature in °C

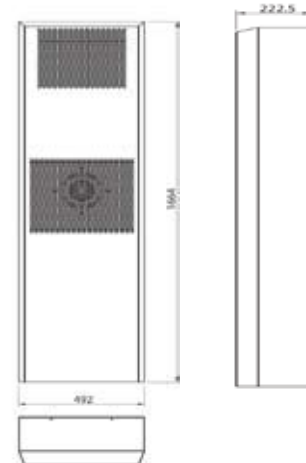

PARAMETRES	AC-WM-30-xx/xx	
Voltage	230-1-50/60	V-ph-Hz
Cooling capacity L35L35 - DIN 3168	3000	W
Cooling capacity L35L50 - DIN 3168	2500	W
Dimensions (HxWxD)	1664x492x223	mm
Max running current	8,5	A
Starting current	46	A
Power absorbed L35L50	1950	W
Side cabinet fan flow, free air	1050	m ³ /h
Side cabinet temperature limits	25 - 45	°C
Side ambient temperature limits	20 - 55	°C
Side cabinet protection degree	54	IP
Noise level	75	dB(A)
Color	7035	RAL

AVAILABLE UNITS

AC-WM-30-42/80 - for 42U, 800mm *
AC-WM-30-42/100 - for 42U, 1000mm *

* Code includes replacement side panel
ROF rack family dimensions – height in U, depth in mm