

# SPACE OPTIMIZATION SECTIONS



End-of-the-row section applied



Front/rear sections applied

➤ **Conteg's Space Optimization Sections** are designed to provide your data center with additional layout flexibility.

## MAIN ADVANTAGES

- Special sections for adding extra space
- Allow layout flexibility via expansion of previously installed racks
- Same size as racks for minimal space consumption
- Can be added to the side, front and/or rear of standard racks

Space optimization sections	Compatible racks
ROF-ES-42-30/80	Ri7/RDF/RSF-42-xx/80
ROF-ES-45-30/80	Ri7/RDF/RSF-45-xx/80
ROF-ES-42-30/100	Ri7/RDF/RSF-42-xx/100
ROF-ES-45-30/100	Ri7/RDF/RSF-45-xx/100
ROF-RS-42-60/30	RSF/Ri7
ROF-RS-45-60/30	RSF/Ri7
ROF-RS-42-80/30	RDF/RSF/Ri7
ROF-RS-45-80/30	RDF/RSF/Ri7

## DESCRIPTION:

### SPACE OPTIMIZATION SECTIONS

- Compatible with RSF, RDF, Ri7 and RM7 series (iSEVEN - different front top shape)
- Expansion of both existing and new solutions – ready for next decade


### FRONT and REAR SECTION

- Increase usable depth by 300 mm modules
- Can be fitted out with extrusions
- Can be used for power management

### END-OF-ROW SECTION

- Additional space for infrastructure use with wide 300 mm module
- Can be used for power management

## END-OF-THE-ROW SECTION

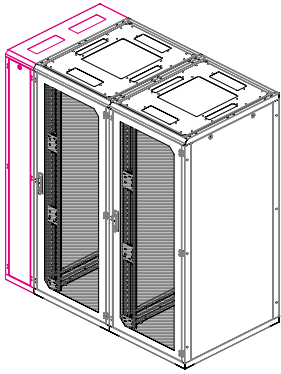


End-of-the-row section

- For cable management, patching and power distribution at end of cabinet row
- Frame design
- Front and rear panels with locks, no side panels
- Cable entries in top and bottom covers
- Accepts vertical cable management systems (e.g. perforated flat panels, basket trays)
- Package includes: 1x rack, 1x DP-DR-UNI, 4x feet

Code	H (in U)	Dimensions (mm)		Compatible racks
		W	D	
ROF-ES-42-30/80	42	300	800	RSF*, RDF*, R17, RM7
ROF-ES-42-30/100	42	300	1000	
ROF-ES-45-30/80	45	300	800	
ROF-ES-45-30/100	45	300	1000	

\* Optimized

## FRONT/REAR SECTION

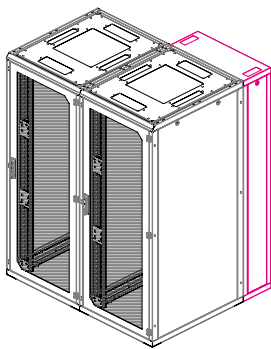

Front/rear section

- Expands available space at rear/front of rack, allowing for installation of deeper equipment
- Further possibility for patching and power distribution
- Cable entries in top and bottom covers
- Tinted glass door with swivel handle; full range of RSF family door options (security glass, sheet steel, perforated sheet steel, vented, active vented, etc.)
- Accepts 19" vertical extrusions or vertical cable management systems
- Package includes: 1x rack with glass door, 1x DP-DR-UNI, 4x feet

Code	H (in U)	Dimensions (mm)		Compatible racks
		W	D	
ROF-RS-42-60/30	42	600	300	RSF, RDF, R17, RM7
ROF-RS-45-60/30	45	600	300	
ROF-RS-42-80/30	42	800	300	
ROF-RS-45-80/30	45	800	300	

## RELATED ACCESSORIES

Code	Description	Note
DP-RS-VP-42/30/19-A	(H) 42U, (W) 300 mm, 9x 19" positions	VERTICAL PANELS FOR FRONT/REAR SECTIONS – vertical panels required for installing relevant 19" and 10" equipment (patch panels, PDUs, switches) and 14 or 15 RJ-45 panels in the front/rear section
DP-RS-VP-45/30/19-A	(H) 45U, (W) 300 mm, 9x 19" positions	
DP-RS-VP-42/30/10-A	(H) 42U, (W) 300 mm, 24x 10" positions	
DP-RS-VP-45/30/10-A	(H) 45U, (W) 300 mm, 24x 10" positions	
DP-RS-VP-42/30/RJ-A	(H) 42U, (W) 300 mm, 14x positions for RJ-45 panels, 6xRJ-45 modules each panel	
DP-RS-VP-45/30/RJ-A	(H) 45U, (W) 300 mm, 15x positions for RJ-45 panels, 6xRJ-45 modules each panel	
DP-RS-RJ-14-XX	14 empty panels for snap in, 6x RJ-45 modules each; check with sales for compatibility of the respective RJ-45 brand	
DP-ES-VP-42/30/19-A	(H) 42U, (W) 300 mm, 9x 19" positions	
DP-ES-VP-45/30/19-A	(H) 45U, (W) 300 mm, 9x 19" positions	

[www.conteg.com](http://www.conteg.com)



**CONTEG, spol. s r.o.**

**Headquarters:**

Na Vítěznej pláni 1719/4  
140 00 Prague 4  
Czech Republic  
Tel.: +420 261 219 182  
[conteg@conteg.com](mailto:conteg@conteg.com)  
[www.conteg.com](http://www.conteg.com)

**Production plant:**

K Silu 2179  
393 01 Pelhřimov  
Czech Republic  
Tel.: +420 565 300 300

**Local Branches/Offices:**

Austria/Germany/Switzerland:	+420 261 219 182
Benelux:	+31 76 5420 709
Southeastern Europe:	+49 172 8484 346
Finland:	+358 50 414 1257
France/Italy/Maghreb:	+33 1 60 04 55 90
Middle East:	+971 55 508 3241
Russia/CIS:	+7 495 967 3840
Saudi Arabia:	+966 54 000 2341

**CONTEG**